

Part No: 826-140X6C

Schedule 80 PVC & CPVC

Expansion Joint

Desc: 14 CPVC EXPANSION JOINT SOCX6 FKM

MSRP: 16726.33

Part Code: 085

Weight(lbs): 173.144

Weight(kg): 78.537

Weight(gm): 78537

Size: 14"


Color: GRAY

Material: CPVC

Connection Fabricated Socket

Travel Length 6" Travel

NOTE T = TRAVEL

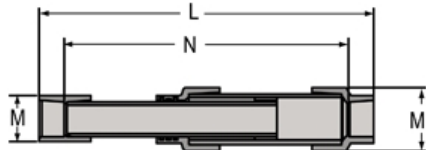

L-OPEN = 46-3/4

N- = 26
CLOSED

N-OPEN = 32

T = 6

M = 15-1/2

M1 = 16

L- = 40-3/4
CLOSED

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

