

Part No: 827-007

Schedule 80 PVC & CPVC

Elbow

Desc: 3/4 PVC 45 ST ELL SPIGOTXSOC SCH80

MSRP: 15.97

Part Code: 080

Weight(lbs): 0.097

Weight(kg): 0.044

Weight(gm): 44

Size: 3/4"


Color: GRAY

Material: PVC

Connection Spigot x Socket

Angle 45°

Type Standard

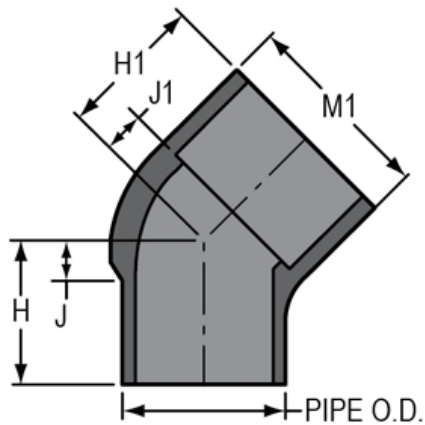

H = 1-9/16

H1 = 1-3/8

J = 17/32

J1 = 3/8

M1 = 1-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

