

Part No: 827-100

Schedule 80 PVC & CPVC

Elbow

Desc: 10 PVC 45 ST ELL SPIGOTXSOC SCH80

MSRP: 2174.98

Part Code: 081

Weight(lbs): 24.582

Weight(kg): 11.15

Weight(gm): 11150

Size: 10"


Color: GRAY

Material: PVC

Connection Spigot x Socket

Angle 45°

Type Standard

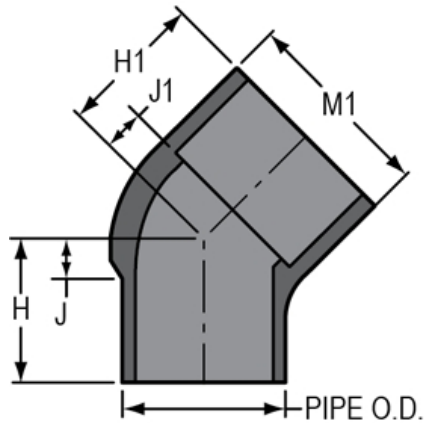

H = 10-5/8

H1 = 7-21/32

J = 5-5/8

J1 = 2-5/8

M1 = 12

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

