

Part No: 827-100C

Schedule 80 PVC & CPVC

Elbow

Desc: 10 CPVC 45 ST ELL SPIGOTXSOC SCH80

MSRP: 3324.69

Part Code: 091

Weight(lbs): 25.463

Weight(kg): 11.55

Weight(gm): 11550

Size: 10"


Color: GRAY

Material: CPVC

Connection Spigot x Socket

Angle 45°

Type Standard

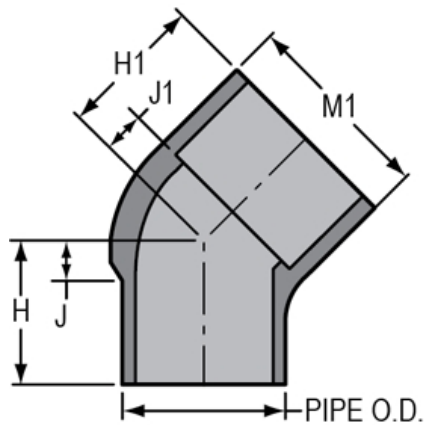

H = 10-5/8

H1 = 7-21/32

J = 5-5/8

J1 = 2-5/8

M1 = 12

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

