

Part No: 828-240F

Fabricated Fittings

Coupling

Desc: 24 PVC REPAIR COUPLING GASKET S80

MSRP: 5325.13

Part Code: 083

Weight(lbs): 142.628

Weight(kg): 64.695

Weight(gm): 64695

Size: 24"


Color: GRAY

Material: PVC

Schedule SCH 80

Connection Gasket X Gasket

Type Standard

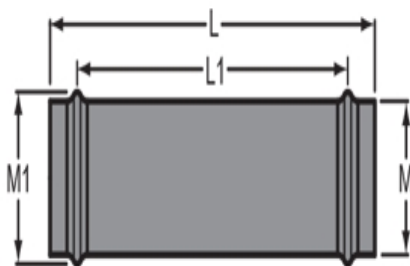

L = 32

L1 = 23-1/2

M = 26-7/16

M1 = 28-13/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

