

Part No: 829-140C

Schedule 80 PVC & CPVC

Coupling

Desc: 14 CPVC COUPLING SOC SCH80

MSRP: 1671.41

Part Code: 095

Weight(lbs): 28.131


Weight(kg): 12.76

Weight(gm): 12760

Size: 14"

Color: GRAY

Material: CPVC

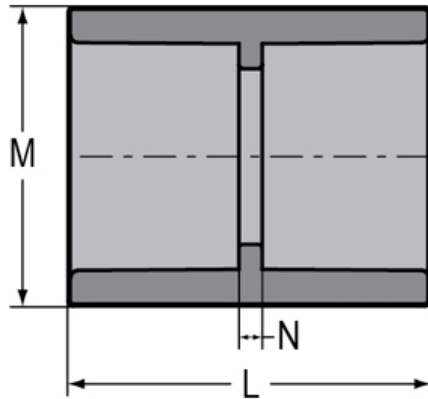

Connection Socket x Socket

Type Standard

L = 14- 7/16

M = 15- 5/8

N = 3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

