

Part No: 829-760CFE

Fabricated Fittings

Coupling

Desc: 16X10CPVC ECC REDCOUPLNGSOC SCH80

MSRP: 7858.76

Part Code: 097

Weight(lbs): 67.241

Weight(kg): 30.5

Weight(gm): 30500

Size: 16"X10"


Color: GRAY

Material: CPVC

Schedule SCH 80

Connection Socket X Socket

Type Eccentric Reducer

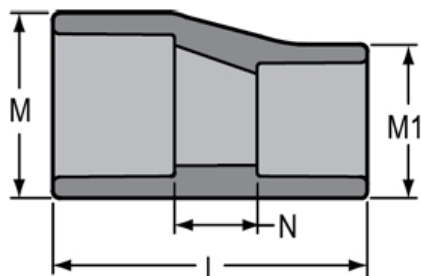

L = 37

M = 17- 1/2

M1 = 11-15/16

N = 23- 3/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

