

Part No: 829-786CF

Fabricated Fittings

Coupling

Desc: 18X6 CPVC RED COUPLING SOC SCH80

MSRP: 9566.68

Part Code: 097

Weight(lbs): 104.812

Weight(kg): 47.542

Weight(gm): 47542

Size: 18"X6"


Color: GRAY

Material: CPVC

Schedule SCH 80

Connection Socket X Socket

Type Reduction

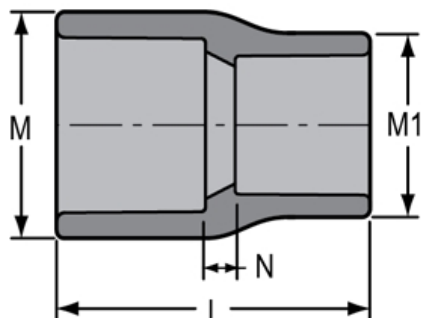

L = 43- 7/8

M = 19-11/16

M1 = 7- 1/2

N = 31- 5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

