

Part No: 835-010CESR

Schedule 80 PVC & CPVC

Adapter

Desc: 1 CPVC ENCP FEM ADAPTER SOCXSRFPT SCH80

MSRP: 33.6

Part Code: 096

Weight(lbs): 0.146

Weight(kg): 0.066

Weight(gm): 66


Size: 1"

Color: GRAY

Material: CPVC

Connection Socket x Encapsulated SR Fipt

Type Standard

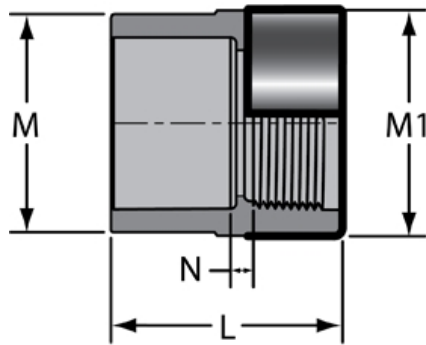

L = 2- 1/4

M = 1-23/32

M1 = 1-25/32

N = 3/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

