

Part No: 835-010SRBL

Low Extractable

Adapter

Desc: 1 PVC LE FEM ADAPTER SOCXSRPT SCH80

MSRP: 22.31

Part Code: 065

Weight(lbs): 0.139


Weight(kg): 0.063

Weight(gm): 63

Size: 1"

Color: BLUE

Material: PVC LE

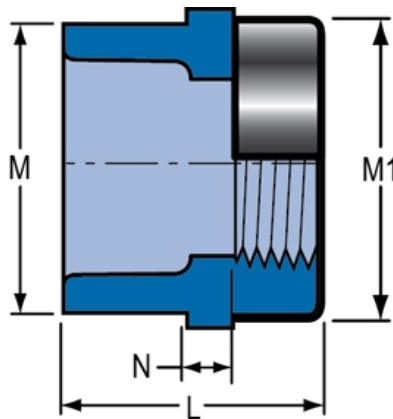

Connection Socket x SR Fipt
Type SR Female Adapter

L = 2- 5/32

M = 1- 23/32

M1 = 1- 23/32

N = 3/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

