

Part No: 835-012CSS

Schedule 80 PVC & CPVC

Adapter

Desc: 1-1/4 CPVC FEM ADAPTER SOCXSSFPT SCH80

MSRP: 414.37

Part Code: 096

Weight(lbs): 0.289

Weight(kg): 0.131

Weight(gm): 131


Size: 1-1/4

Color: GRAY

Material: CPVC

Connection Socket X SS Fipt

Type Standard

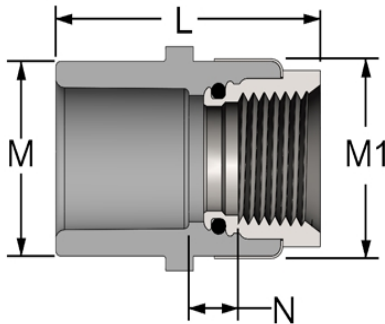

L = 2-3/8

M = 2-3/32

M1 = 2-1/16

N = 3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

