

Part No: 835-012SRBL

Low Extractable

Adapter

Desc: 1-1/4 LE FEM ADAPTER SOCXSRFPT SCH80

MSRP: 28.8

Part Code: 065

Weight(lbs): 0.19


Weight(kg): 0.086

Weight(gm): 86

Size: 1-1/4"

Color: BLUE

Material: PVC LE

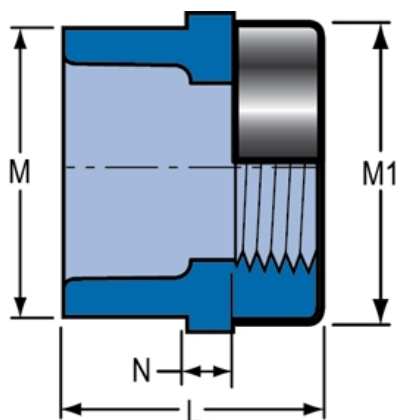

Connection Socket x SR Fipt

Type SR Female Adapter

L = 2- 5/16

M = 2- 1/8

M1 = 2- 1/16

N = 3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

