

Part No: 835-020CSS

Schedule 80 PVC & CPVC

Adapter

Desc: 2 CPVC FEM ADAPTER SOCXSSFPT SCH80

MSRP: 632.63

Part Code: 096

Weight(lbs): 0.847


Weight(kg): 0.384

Weight(gm): 384

Size: 2

Color: GRAY

Material: CPVC

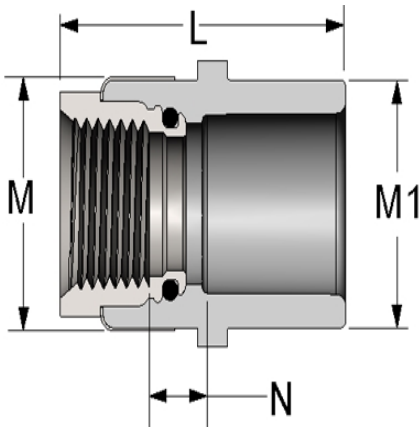

Connection Socket X SS Fipt
Type Standard

M = 2-7/8

M1 = 3

N = 7/16

L = 2-11/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

