

Part No: 835-060SR

Schedule 80 PVC & CPVC

Adapter

Desc: 6 PVC FEMALE ADAPTER SOCXSR/FPT SCH80

MSRP: 155.46

Part Code: 086

Weight(lbs): 3.261


Weight(kg): 1.479

Weight(gm): 1479

Size: 6"

Color: GRAY

Material: PVC

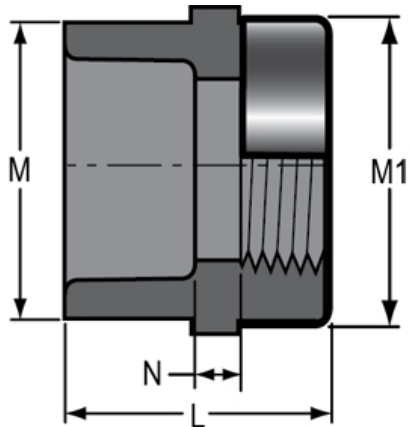

Connection Socket x SR Fipt
Type Standard

L = 4-31/32

M = 7-21/32

M1 = 7-21/32

N = 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

