

Part No: 835-131BR

Schedule 80 PVC & CPVC

Adapter

Desc: 1X3/4 PVC RED FEM ADPT SOCXBRFPT SCH80

MSRP: 105.82

Part Code: 086

Weight(lbs): 0.181

Weight(kg): 0.082

Weight(gm): 82


Size: 1 X 3/4

Color: GRAY

Material: PVC

Connection Socket x Brass Fipt

Type Reduction

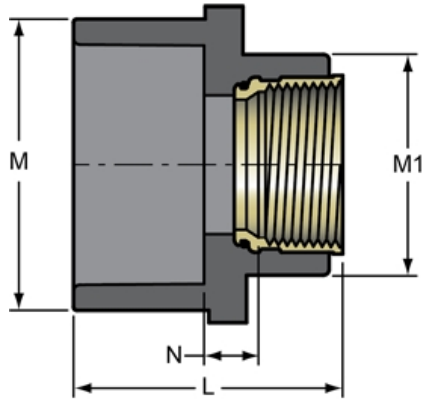

L = 2-5/16

M = 1-11/16

M1 = 1-3/8

N = 17/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

