

Part No: 8398-040

Schedule 80 PVC & CPVC

Union

Desc: 4 PVC TRANS UNION EPDM BSPXNPT

MSRP: 426.31

Part Code: 197

Weight(lbs): 3.988

Weight(kg): 1.809

Weight(gm): 1809


Size: 4"

Color: GRAY

Material: PVC

Connection Bspst Thread x ASTM Fipt

O-Ring EPDM

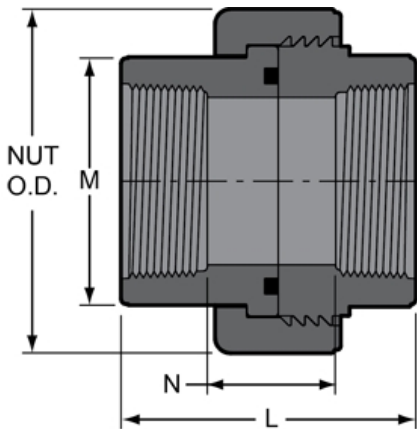

L = 5- 7/8

M = 5-3/8

N = 2-3/4

NUT = 7-1/8
O.D.

M1 = 5-17/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

