

Part No: 844-005C

Schedule 80 PVC & CPVC

Tee

Desc: 1/2 CPVC STREET TEE SPIGOTXSOCXSOC SCH80

MSRP: 29.74

Part Code: 090

Weight(lbs): 0.108

Weight(kg): 0.049

Weight(gm): 49


Size: 1/2"

Color: GRAY

Material: CPVC

Connection Spigot x Socket x Socket

Type Standard

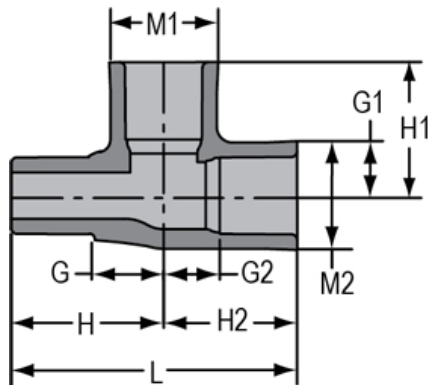

G = 25/32 **G1** = 19/32 **G2** = 19/32 **H** = 1-11/16 **H1** = 1-15/32
H2 = 1-15/32 **L** = 3- 5/32 **M1** = 1- 3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

