

Part No: 854-005BL

Low Extractable

Flange

Desc: 1/2 PVC LE V/S FLANGE SOC CL150 150PSI

MSRP: 35.96

Part Code: 065

Weight(lbs): 0.187

Weight(kg): 0.085

Weight(gm): 85

Size: 1/2"


Color: BLUE

Material: PVC LE

Type Flange Van Stone Style

Connection Socket

Pressure Rating 150 psi @ 73° F

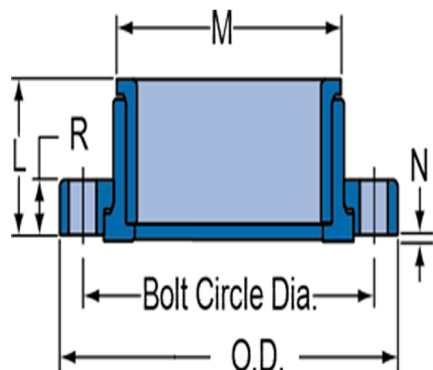

L = 1- 1/32

M = 1- 7/32

N = 5/32

O.D. = 3- 1/2

R = 17/32

No of Bolts = 4

Bolt Circle Dia. = 2- 3/8

Bolt Size = 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

