

Part No: 854-010CL300

Flanges & Cut-In Kit

Molded

Desc: 1 PVC VAN STONE FLANGE SOC CL300 150PSI

MSRP: 455.77

Part Code: 083

Weight(lbs): 1.457

Weight(kg): 0.661


Weight(gm): 661

Size: 1"

Color: GRAY

Material: PVC

Connection Socket CL 300 (Van Stone 2 Piece)

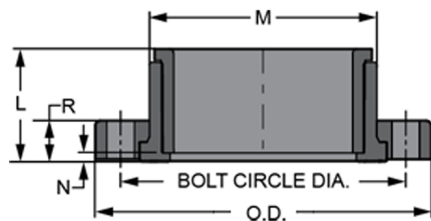

L = 1- 1/4

M = 1- 3/4

N = 3/16

O.D. = 4- 7/8

R = 1

No of Bolts = 4

Bolt Circle Dia. = 3- 1/2

Bolt Size = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

