

Part No: 854-012CL300

Flanges & Cut-In Kit

Molded

Desc: 1-1/4 PVC V/S FLANGE SOC CL300 150PSI

MSRP: 465.36

Part Code: 083

Weight(lbs): 1.951

Weight(kg): 0.885


Weight(gm): 885

Size: 1-1/4"

Color: GRAY

Material: PVC

Connection Socket CL 300 (Van Stone 2 Piece)

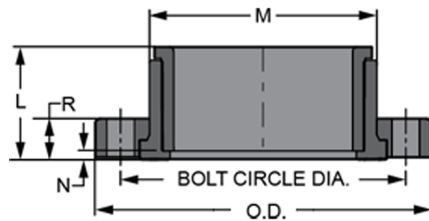

O.D. = 5- 1/4

R = 1

No of Bolts = 4

Bolt = 3- 7/8
Circle Dia.

Bolt Size = 5/8

M = 2- 1/8

N = 1/8

L = 1- 3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

