

Part No: 854-020CL300C

Flanges & Cut-In Kit

Molded

Desc: 2 CPVC VAN STONE FLANGE SOC 150PSI CL300

MSRP: 692.07

Part Code: 097

Weight(lbs): 2.652

Weight(kg): 1.203


Weight(gm): 1203

Size: 2"

Color: GRAY

Material: CPVC

Connection Socket CL 300 (Van Stone 2 Piece)

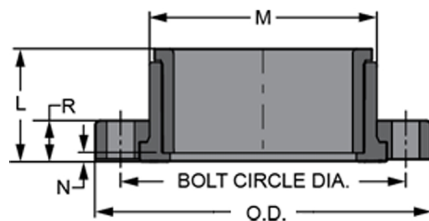

L = 1-11/16

M = 2-15/16

N = 3/16

O.D. = 6- 1/2

R = 1

No of Bolts = 8

Bolt Circle Dia. = 5

Bolt Size = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

