

Part No: 854-025CL300

Flanges & Cut-In Kit

Molded

Desc: 2-1/2 PVC VAN STONE FLG SOC 150PSI CL300

MSRP: 558.87

Part Code: 083

Weight(lbs): 3.684

Weight(kg): 1.671


Weight(gm): 1671

Size: 2-1/2"

Color: GRAY

Material: PVC

Connection Socket CL 300 (Van Stone 2 Piece)

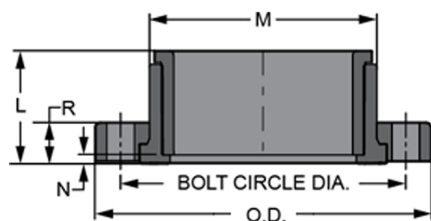

L = 2

M = 3- 9/16

N = 1/4

O.D. = 7- 1/2

R = 1

No of Bolts = 8

Bolt Circle Dia. = 5- 7/8

Bolt Size = 3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

