

Part No: 854-030BL

Low Extractable

Flange

Desc: 3 PVC LE VAN STONE FLG SOC CL150 150PSI

MSRP: 102.32

Part Code: 065

Weight(lbs): 1.59


Weight(kg): 0.721

Weight(gm): 721

Size: 3"

Color: BLUE

Material: PVC LE

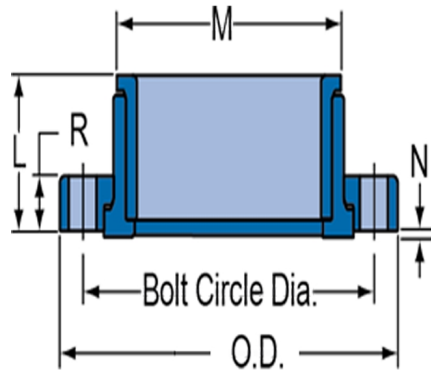

Type Flange Van Stone Style

Connection Socket

Pressure Rating 150 psi @ 73° F

L = 2- 1/8

M = 4- 1/4

N = 1/4

O.D. = 7- 1/2

R = 1-1/8

No of Bolts = 4

Bolt Circle Dia. = 6

Bolt Size = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

