

Part No: 854-030CL300C

Flanges & Cut-In Kit

Molded

Desc: 3 CPVC VAN STONE FLANGE SOC 150PSI CL300

MSRP: 894.96

Part Code: 097

Weight(lbs): 5.481

Weight(kg): 2.486


Weight(gm): 2486

Size: 3"

Color: GRAY

Material: CPVC

Connection Socket CL 300 (Van Stone 2 Piece)

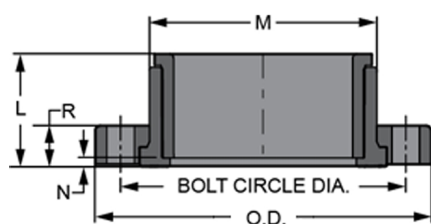

L = 2- 1/8

M = 4- 1/4

N = 1/4

O.D. = 8- 1/4

R = 1

No of Bolts = 8

Bolt Circle Dia. = 6- 5/8

Bolt Size = 3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

