

**Part No:** 854-040DIN

**Flanges & Cut-In Kit**

**Molded**

**Desc:** 4 PVC VANSTONE FLANGE SOC PN10/16 DRILL

**MSRP:** 109.24

**Part Code:** 080

**Weight(lbs):** 2.346

**Weight(kg):** 1.064


**Weight(gm):** 1064

**Size:** 110MM

**Color:** GRAY

**Material:** PVC

**Connection** Socket(ASTM 2 Piece DIN PN)

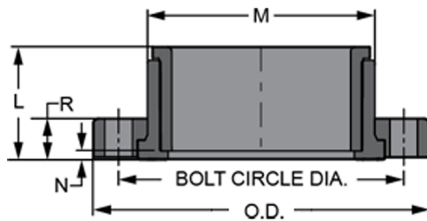

N = 9/32

O.D. = 8-1/2

R = 13/16

No of Bolts = 8

Bolt Circle Dia. = 7-3/32

Bolt Size = 5/8

L = 2-1/2

M = 5-1/4

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

