

Part No: 854-060-1SC

Flanges & Cut-In Kit

Molded

Desc: 6 CPVC V/S SPLIT FLANGE RING W/2-HALVES

MSRP: 478.38

Part Code: 090

Weight(lbs): 2.672

Weight(kg): 1.212


Weight(gm): 1212

Size: 6

Color: GRAY

Material: CPVC

Connection Flange Replacement (Split Rings)

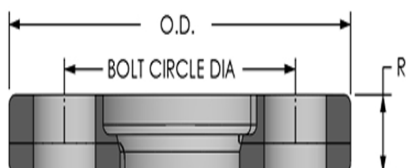

O.D. = 11-5/16

R = 1-9/32

Bolt
Circle
Dia. = 9-1/2

No of
Bolts = 8

Bolt Size = 3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

