

Part No: 854-100CL300C

Flanges & Cut-In Kit

Molded

Desc: 10 CPVC VAN STONE FLG SOC 150 PSI CL300

MSRP: 3467.43

Part Code: 097

Weight(lbs): 46.022

Weight(kg): 20.875


Weight(gm): 20875

Size: 10"

Color: GRAY

Material: CPVC

Connection Socket CL 300 (Van Stone 2 Piece)

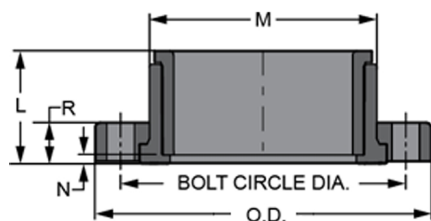

L = 5-11/16

M = 11- 3/4

N = 5/8

O.D. = 17- 1/2

R = 1- 1/2

No of Bolts = 16

Bolt Circle Dia. = 15- 1/4

Bolt Size = 1

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

