

Part No: 854-140CL300C

Flanges & Cut-In Kit

Molded

Desc: 14 CPVC V/S FLANGE SOC CL300 150 PSI

MSRP: 4811.14

Part Code: 097

Weight(lbs): 32.783

Weight(kg): 14.87


Weight(gm): 14870

Size: 14"

Color: GRAY

Material: CPVC

Connection Socket CL 300 (Van Stone 2 Piece)

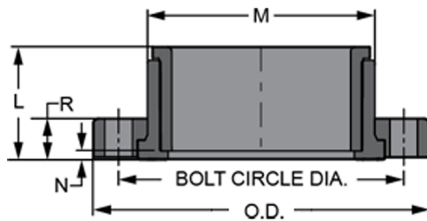

L = 7- 9/16

M = 15- 9/16

Bolt = 20- 1/4
Circle
Dia.

Bolt Size = 1- 1/8

N = 9/16

O.D. = 23

R = 2

No of = 20
Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

