

Part No: 854-160FS

Fabricated Fittings

Flanges and Cut in Kits

Desc: 16 PVC V/S FLANGE SOC CL150 W/STEEL RING

MSRP: 2032.07

Part Code: 083

Weight(lbs): 78.044

Weight(kg): 35.4

Weight(gm): 35400

Size: 16


Color: GRAY

Material: PVC

Joint Style IPS

Connection Socket

Ring Steel

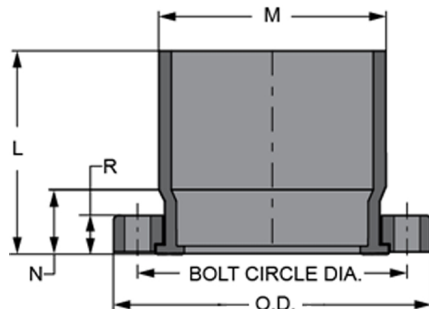

L = 12-5/8

M = 17

N = 4-5/8

R = 1

Bolt Circle Dia. = 21-1/4

No of Bolts = 16

Bolt Size = 1

O.D. = 23-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

