

Part No: 854-180CL300

Flanges & Cut-In Kit

Molded

Desc: 18 PVC VAN STONE FLANGE SOC CL300 50 PSI

MSRP: 5463.52

Part Code: 083

Weight(lbs): 60.301

Weight(kg): 27.352


Weight(gm): 27352

Size: 18"

Color: GRAY

Material: PVC

Connection Socket CL 300 (Van Stone 2 Piece)

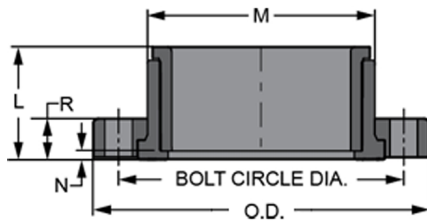

L = 14-7/16

M = 19- 1/8

N = 5-7/16

O.D. = 28

R = 2

No of Bolts = 24

Bolt Circle Dia. = 24- 3/4

Bolt Size = 1- 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

