

Part No: 854-200CFS

Fabricated Fittings

Flanges and Cut in Kits

Desc: 20 CPVC V/S FLANGE SOC CL150 W/STEEL RNG

MSRP: 4249.56

Part Code: 097

Weight(lbs): 105.822

Weight(kg): 48

Weight(gm): 48000

Size: 20


Color: GRAY

Material: CPVC

Joint Style IPS

Connection Socket

Ring Steel

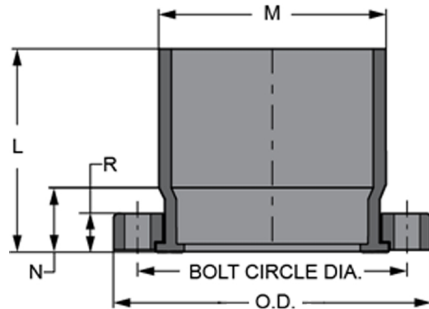

L = 15-5/8

Bolt = 25
Circle
Dia.

Bolt Size = 1- 1/8

M = 21- 3/16

N = 5-5/8

O.D. = 27- 9/16

R = 1

No of = 20
Bolts

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

