

Part No: 854-240CFS

Fabricated Fittings

Flanges and Cut in Kits

Desc: 24 CPVC V/S FLANGE SOC CL150 W/STEEL RNG

MSRP: 6876.96

Part Code: 097

Weight(lbs): 106.483

Weight(kg): 48.3

Weight(gm): 48300

Size: 24"


Color: GRAY

Material: CPVC

Joint Style IPS

Connection Socket

Ring Steel

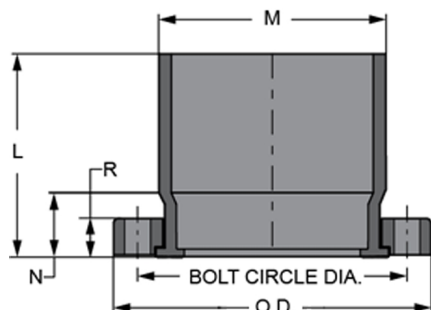

L = 18-5/16

M = 25-3/8

N = 6-5/16

O.D. = 32

R = 1

No of Bolts = 20

Bolt Circle Dia. = 29-1/2

Bolt Size = 1-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

