

Part No: 856-140FP

Fabricated Fittings

Flanges and Cut in Kits

Desc: 14 PVC V/S FLG SPG 150PSI CL150

MSRP: 3236.29

Part Code: 083

Weight(lbs): 41.888

Weight(kg): 19

Weight(gm): 19000

Size: 14"


Color: GRAY

Material: PVC

Joint Style IPS

Connection Spigot

Ring Plastic

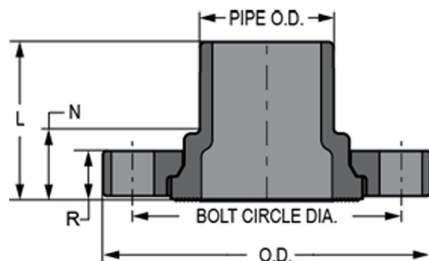

L = 15- 5/16

N = 7-9/16

O.D. = 21

R = 2

No of Bolts = 12

Bolt Circle Dia. = 18- 3/4

Bolt Size = 1

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

