

Part No: 857-015BL

Low Extractable

Union

Desc: 1-1/2 PVC LE UNION SOCXSOC FKM

MSRP: 81.68

Part Code: 065

Weight(lbs): 0.608

Weight(kg): 0.276

Weight(gm): 276

Size: 1-1/2"


Color: BLUE

Material: PVC LE

Connection Socket x Socket

Type Union

O-Ring FKM

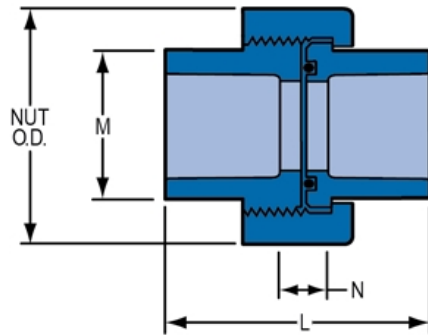

L = 3-5/32

M = 2- 9/16

N = 15/32

NUT = 3-17/32
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

