

Part No: 859-003

Schedule 80 PVC & CPVC

Union

Desc: 3/8 PVC UNION SOCXFPT FKM

MSRP: 41.43

Part Code: 080

Weight(lbs): 0.119

Weight(kg): 0.054

Weight(gm): 54


Size: 3/8"

Color: GRAY

Material: PVC

Connection Socket x Fipt

O-Ring FKM

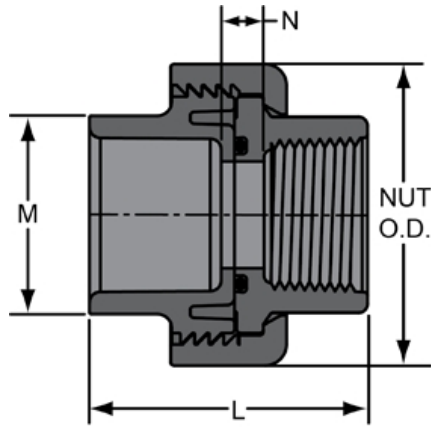

L = 2- 5/32

M = 1-1/16

N = 13/16

NUT = 1-25/32
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

