

Part No: 859-007BR

Schedule 80 PVC & CPVC

Union

Desc: 3/4 PVC UNION SOCXBRFPT FKM SCH80

MSRP: 89.34

Part Code: 086

Weight(lbs): 0.355

Weight(kg): 0.161

Weight(gm): 161


Size: 3/4"

Color: GRAY

Material: PVC

Connection Socket x Brass Fipt

O-Ring FKM

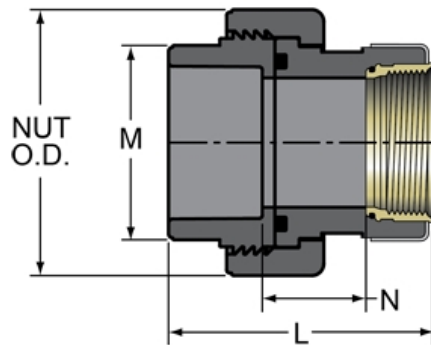

L = 2-11/16

M = 1-17/32

N = 1

NUT = 2- 1/2
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

