

Part No: 8622-015

Valves

Quiet Swing Check

Desc: 1-1/2 PVC Q-CHECK VALVE SOC SCH40

MSRP: 70.73

Part Code: 026

Weight(lbs): 1.369

Weight(kg): 0.621

Weight(gm): 621

Size: 1-1/2"


Color: WHITE

Material: PVC

Type Quiet Swing Check

Connection Socket (TU)

Pressure Rating 150 psi @ 73° F Full Flow (Open)
75 psi Back Pressure (Closed)

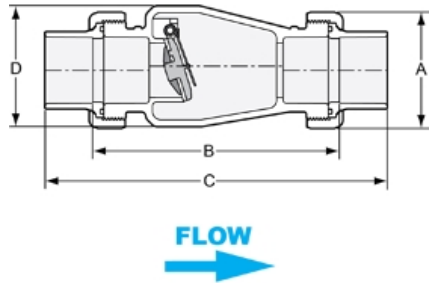

A = 3-5/16

B = 7-3/32

C = 9-7/8

D = 3-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

