

Part No: 866V-251C

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 2X1-1/2 CPVC CLAMP SADDLE SOC FKM ZN B

MSRP: 95.21

Part Code: 096

Weight(lbs): 0.787

Weight(kg): 0.357

Weight(gm): 357

Size: 2"X1-1/2"

Color: GRAY


Material: CPVC

Connection Single Socket

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

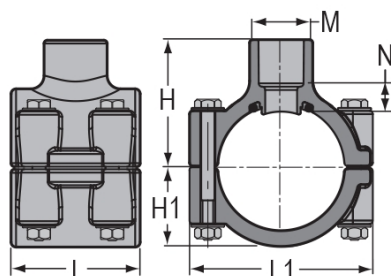

H = 2-15/16

H1 = 1- 1/2

L = 2- 7/16

L1 = 3- 7/16

M = 2-13/32

N = 11/32

No of Bolts = 4

Bolt = 8

Hole Size = 1-1/2

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

