

Part No: 866V-291C

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 2-1/2X1-1/2 CPVC CLAMP SADDLE SOC FKM

MSRP: 132.31

Part Code: 096

Weight(lbs): 1.124

Weight(kg): 0.51

Weight(gm): 510

Size: 2-1/2"X1-1/2"

Color: GRAY


Material: CPVC

Connection Single Socket

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

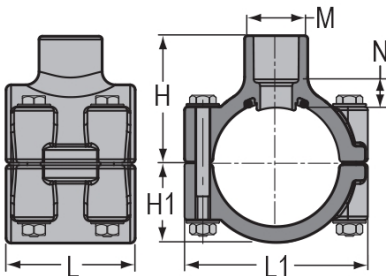

H = 3-3/16

H1 = 1-3/4

L = 4-1/8

L1 = 4-1/8

M = 2-13/32

N = 11/32

Bolt = 8

Hole Size = 1-3/4

No of = 4

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

