

Part No: 866V-418C

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 4X1-1/4 CPVC CLAMP SADDLE SOC FKM ZN B

MSRP: 159.01

Part Code: 096

Weight(lbs): 1.775

Weight(kg): 0.805

Weight(gm): 805

Size: 4"X1-1/4"

Color: GRAY


Material: CPVC

Connection Single Socket

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

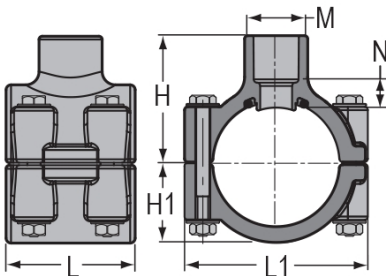

H = 4-3/8

H1 = 2-5/8

L = 4-1/8

L1 = 5-13/16

M = 2-7/16

N = 27/32

No of Bolts = 4

Bolt = 8

Hole Size = 1-3/4

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

