

Part No: 866V-526

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 6X1-1/4 PVC CLAMP SADDLE SOC FKM ZN BL

MSRP: 157.92

Part Code: 086

Weight(lbs): 3.441

Weight(kg): 1.561

Weight(gm): 1561

Size: 6"X1-1/4"

Color: GRAY


Material: PVC

Connection Single Socket

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

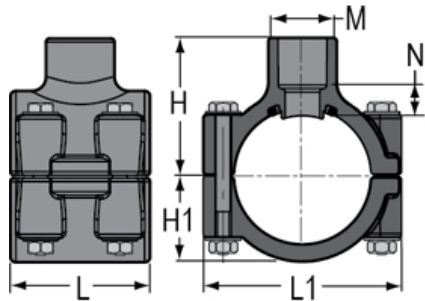

No of Bolts = 4

L = 4- 1/8

L1 = 8-3/16

M = 3

N = 1-1/8

Bolt = 10

Hole Size = 2-1/4

H = 5-11/16

H1 = 3-13/16

Torque FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

