

Part No: 867SV-337CSR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 3X1-1/2 CPVC CLAMP SADDLE SRFPT FKM SS

MSRP: 243.03

Part Code: 096

Weight(lbs): 1.545

Weight(kg): 0.701

Weight(gm): 701

Size: 3"X1-1/2"

Color: GRAY


Material: CPVC

Connection Single SR Fipt

Type Clamp Saddle

Hardware SS

O-Ring FKM

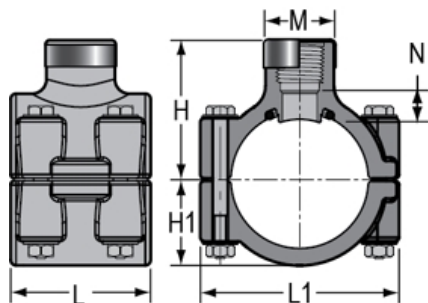

H = 3-7/8

H1 = 2

L = 4-1/8

L1 = 4-3/4

M = 3-1/32

N = 1-3/16

Bolt = 8

Hole Size = 2-1/4

No of = 4

Torque
FT./LBS.

Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

