

Part No: 867SV-527SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 6X1-1/2 PVC CLAMP SADDLE SRFPT FKM SS BL

MSRP: 269.19

Part Code: 086

Weight(lbs): 3.303

Weight(kg): 1.498

Weight(gm): 1498

Size: 6"X1-1/2"

Color: GRAY


Material: PVC

Connection Single SR Fipt

Type Clamp Saddle

Hardware SS

O-Ring FKM

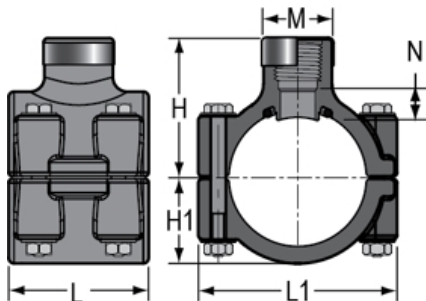

No of Bolts = 4

N = 1-7/16

Bolt Torque = 10
FT./LBS.

Hole Size = 2-1/4

H1 = 3-13/16

L = 4- 1/8

L1 = 8-3/16

M = 3-1/32

H = 5-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

