

Part No: 867SV-582SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 8X4 PVC CLAMP SADDLE SRFPT FKM SS BOLT

MSRP: 588.92

Part Code: 086

Weight(lbs): 8.818

Weight(kg): 4

Weight(gm): 4000

Size: 8"X4"

Color: GRAY


Material: PVC

Connection Single SR Fipt

Type Clamp Saddle

Hardware SS

O-Ring FKM

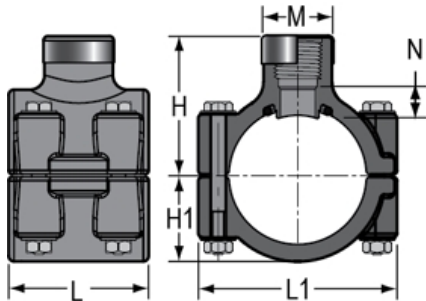

H = 7- 5/16

H1 = 4- 7/8

L = 8- 1/2

L1 = 10-1/16

M = 5- 1/4

N = 1- 1/2

Bolt = 10
Torque
FT./LBS.

Hole Size = 4

No of = 6
Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

