

Part No: 867V-529SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 6X2-1/2 PVC CLAMP SADDLE SRFPT FKM ZN BL

MSRP: 237.62

Part Code: 086

Weight(lbs): 5.062

Weight(kg): 2.296

Weight(gm): 2296

Size: 6"X2-1/2"

Color: GRAY


Material: PVC

Connection Single SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

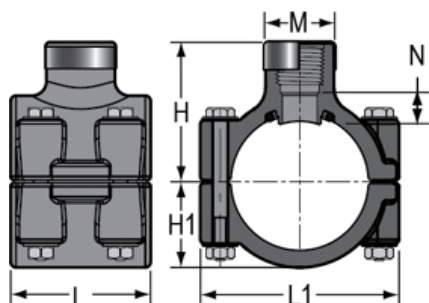

Hole Size = 3

No of Bolts = 4

M = 4-5/16

N = 1-13/32

Bolt Torque = 10
FT./LBS.

H = 6-9/32

H1 = 3-13/16

L = 6

L1 = 8-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

