

Part No: 867V-576SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 8X1-1/4 PVC CLAMP SDL SRFPT FKM ZN BLT

MSRP: 373.54

Part Code: 086

Weight(lbs): 8.499

Weight(kg): 3.855

Weight(gm): 3855

Size: 8"X1-1/4"

Color: GRAY


Material: PVC

Connection Single SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

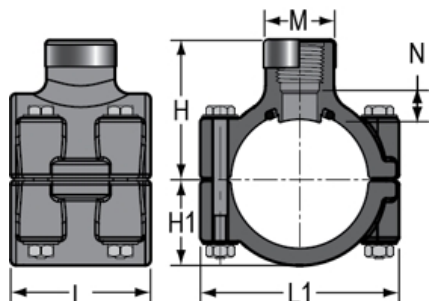

H = 6-3/4

H1 = 4-7/8

L = 8-1/2

L1 = 10-1/16

M = 3-1/32

N = 1-7/16

Bolt = 10
Torque
FT./LBS.

Hole Size = 2-1/8

No of = 6
Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

