

Part No: 867V-585SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 8X6 PVC CLAMP SADDLE SRFPT FKM ZN BOLT

MSRP: 509.04

Part Code: 086

Weight(lbs): 10.536

Weight(kg): 4.779

Weight(gm): 4779

Size: 8"X6"

Color: GRAY


Material: PVC

Connection Single SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

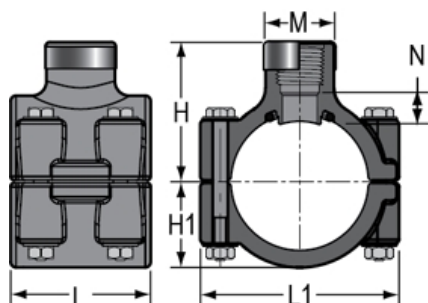

H = 8-1/16

H1 = 4- 7/8

L = 8- 1/2

L1 = 10-1/16

M = 7-21/32

N = 2-1/4

Bolt = 10

Hole Size = 6

No of = 6

Torque
FT./LBS.

Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

