

Part No: 868-419

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 4X1-1/2 PVC CLAMP SADDLE D/O SOC EPDM ZN

MSRP: 112.27

Part Code: 086

Weight(lbs): 1.801

Weight(kg): 0.817

Weight(gm): 817

Size: 4"X1-1/2"

Color: GRAY


Material: PVC

Connection Double Socket

Type Clamp Saddle

Hardware Zinc

O-Ring EPDM

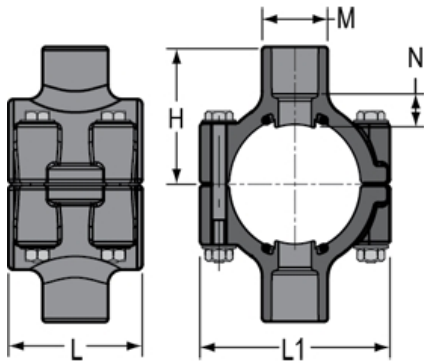

H = 4-1/16

L = 4-1/8

L1 = 5-13/16

M = 2-7/16

N = 13/32

Hole Size = 1-3/4

Bolt = 8
Torque
FT./LBS.

No of = 4
Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

