

Part No: 868-624C

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 10X4 CPVC CLAMP SADDLE D/O SOC EPDM ZN B

MSRP: 1012.86

Part Code: 096

Weight(lbs): 13.486

Weight(kg): 6.117

Weight(gm): 6117

Size: 10"X4"

Color: GRAY


Material: CPVC

Connection Double Socket

Type Clamp Saddle

Hardware Zinc

O-Ring EPDM

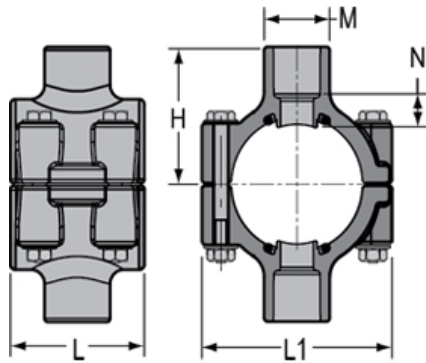

H = 8-7/16

L = 8- 1/2

L1 = 12-1/4

M = 5- 1/4

N = 13/16

Bolt = 10

No of

Hole Size = 4

Torque
FT./LBS.

Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

