

Part No: 868S-418

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 4X1-1/4 PVC CLAMP SADDLE D/O SOC EPDM SS

MSRP: 170.82

Part Code: 086

Weight(lbs): 1.885

Weight(kg): 0.855

Weight(gm): 855

Size: 4"X1-1/4"

Color: GRAY


Material: PVC

Connection Double Socket

Type Clamp Saddle

Hardware SS

O-Ring EPDM

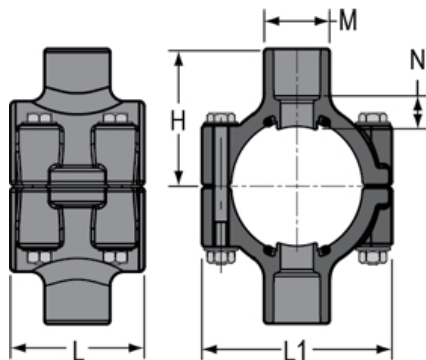

H = 4-3/8

L = 4-1/8

L1 = 5-13/16

M = 2-7/16

N = 27/32

Hole Size = 1-3/4

Bolt = 8
Torque
FT./LBS.

No of = 4
Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

